




Rex®

Stearns®

McGILL®

WARNER
ELECTRIC™

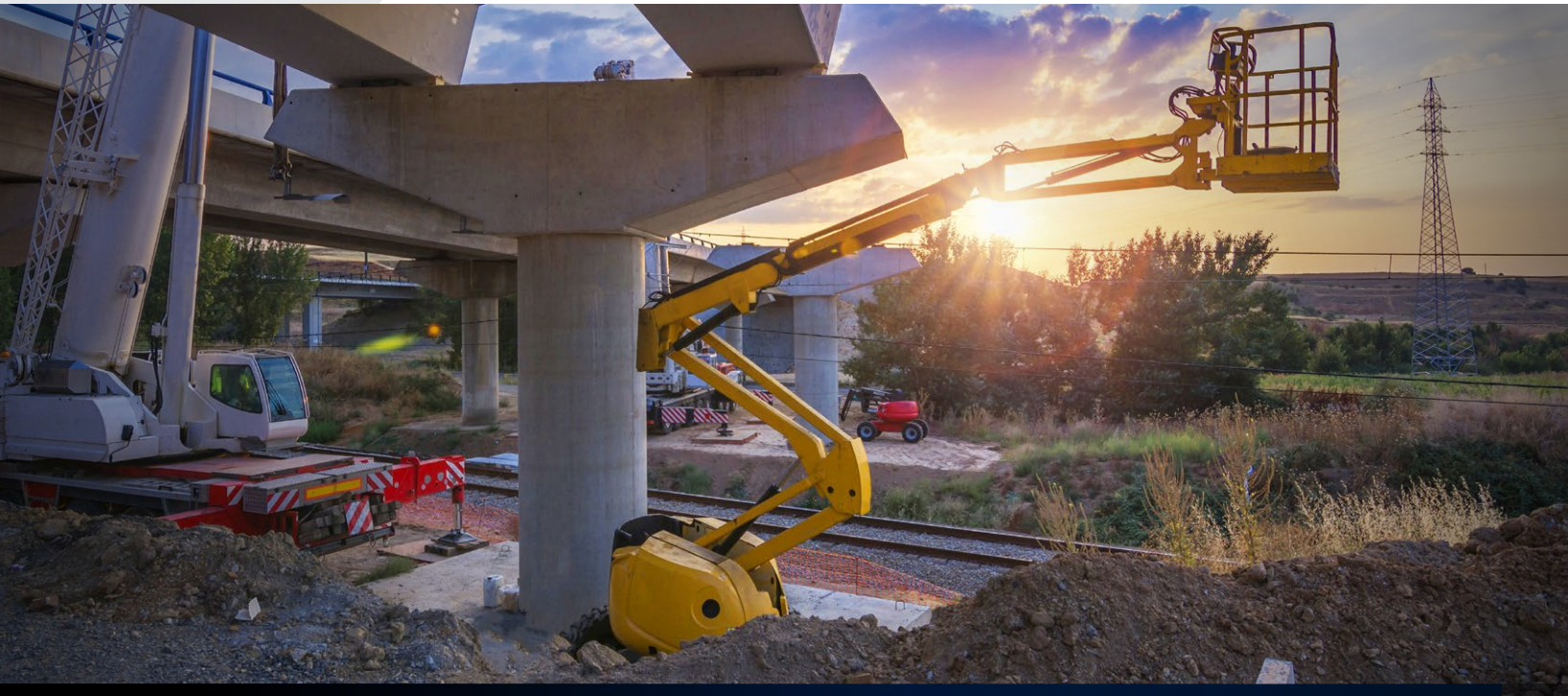

REGAL REXNORD SOLUTIONS FOR FORKLIFTS AND OTHER LIFT TRUCKS



 **RegalRexnord™**

REGAL REXNORD SOLUTIONS for Every Part of your Industrial Lift Truck

Regal Rexnord is a trusted source of single components and Powertrain Solutions for the powered industrial forklift industry. Available as standard or custom, our chain, bearings, rollers, couplings, and brakes are used in all classes of forklifts and utility vehicles worldwide. Our team has decades of experience with every facet of the forklift design: riders, narrow aisles, hand trucks, counterbalance, reach, walkies, and more.



● CENTA™ COUPLINGS

Robust materials and precision-engineered design offer an excellent means of power transmission for high-vibration, high-temperature hydrostatic drives.

● REX™ CHAIN

Pick the right chain from Regal Rexnord's industry standard **RexPro** or upgrade to **RexProX™** with 5x longer maintenance intervals and 2x wear life, all with Silver Label trackability built in.

● DURALON™ BEARINGS

Non-metallic, self-lubricating, maintenance-free bearing technology provides millions of cycles, optimizing application performance life and extending durability beyond traditional bearing options.

● MCGILL™ ROLLER AND NEEDLE BEARINGS

Designed for performance in heavy load and indoor/outdoor environments, these bearings provide long operating life, with some designs requiring no maintenance.

● STEARNS™ BRAKES

High-performance brakes designed to withstand the most demanding environments, reduce noise levels, and increase user safety.

● WARNER ELECTRIC™ BRAKES

Full range of customizable safety braking solutions for reliable parking and stopping performance in electrified forklift applications. Featuring in-house friction material for delivering the best cost-to-size/performance ratio in static and dynamic applications.



More products for more platforms from Regal Rexnord

	CENTA Couplings	Rex Chain	Duralon Bearings	McGill Bearings	Stearns Brakes	Warner Electric Brakes
Forklift Type	Class 1 – Electric Motor Rider	✓	✓	✓	✓	✓
	Class 2 – Electric Motor Narrow Aisle	✓	✓	✓	✓	✓
	Class 3 – Electric Motor Hand Trucks	✓	✓	✓	✓	✓
	Class 4 – Industrial Combustion Engine – Solid/Cushion Tires	✓	✓	✓	✓	
	Class 5 – Industrial Combustion Engine – Pneumatic Tires	✓	✓	✓	✓	
	Class 6 – Electric and Internal Combustion Engine Tractors	✓	✓	✓	✓	✓
	Class 7 – Rough Terrain Forklift	✓	✓	✓	✓	✓

HIGHLY ENGINEERED PRODUCTS for Longer Life

Regal Rexnord™ products contain only robust materials and utilize precision engineering to increase safety, improve wear-life, and extend maintenance intervals. Increase uptime and save money with our pre- and post-purchase online tools and dedicated local technical support teams.



CENTA™ COUPLINGS

- Oil-resistant, shock-resistant and temperature stabilized polyamide
- Combination of steel and shock-resistant glass-fiber reinforced plastic
- Adaptable installation configurations with SAE and non-standard flange sizes

For more information about CENTA Couplings visit rxn.bz/centa-couplings



REX™ CHAIN

- Shot peened pins and link plate design for increased longevity
- Heavy-duty German steel with patented RexPro Lubrication
- 2x the wear life of other low quality, imported chain
- Tailored strands cut to specific lengths; provides anchors and chain and anchor assemblies
- Specialty high performance and light duty economy options available

For more information about Rex Chain visit rxn.bz/leaf-chain



DURALON™ BEARINGS

- Unique self-lubricating woven fiber liner that has low friction and high wear resistance
- Highly engineered polymer composite backing structure, giving high strength and good impact resistance
- Standard sizes and highly adaptable configurations that are engineered to the specific application

For more information about Duralon Bearings visit rxn.bz/duralon-bearings



MCGILL™ ROLLER AND NEEDLE BEARING

- Heavy duty designs for supporting high loads and sealed to operate in a variety of environments
- Well suited for oscillating applications
- Available in a wide variety of sizes and sealing options

For more information about McGill Needle Bearings visit regalrexnord.com/mcgill



STEARNS™ BRAKES

- Fail-safe design calibrated to your specific load, grade, and speed
- Maintenance-free operation designed to outlast the expected life of the forklift
- Customizable designs for challenging footprint and torque requirements

For more information about Stearns Brakes visit rxn.bz/stearns_brakes



WARNER ELECTRIC™ BRAKES

- Reliable, proven, and customizable safety braking solutions
- Advanced non-stick friction material for outdoor environments and cold rooms
- Customized solutions address specific performance needs and installation requirements

For more information about Warner Electric visit rxn.bz/warnerelectric



APPLICATIONS



Beverage



Construction



Cold Storage



Distribution



Food Storage



General Manufacturing



General Warehousing



Retail



Rex[®]



Stearns[®]

McGILL[®]

WARNER
ELECTRIC[™]

Regal Rexnord

Contact us: [rexnord.com/contact](https://www.regalrexnord.com/contact)

[regalrexnord.com](https://www.regalrexnord.com)

The proper selection and application of products and components, including assuring that the product is safe for its intended use, are the responsibility of the customer. To view our Application Considerations, please visit <https://www.regalrexnord.com/Application-Considerations>. To view our Standard Terms and Conditions of Sale, please visit <https://www.regalrexnord.com/Terms-and-Conditions-of-Sale> (which may redirect to other website locations based on product family).

"Regal Rexnord" is not indicative of legal entity. Refer to product purchase documentation for the applicable legal entity. Regal Rexnord, Rex, Centa, Duralon, McGill, Stearns and Warner Electric are trademarks of Regal Rexnord Corporation or one of its affiliated companies.

© 2021, 2023, 2024 Regal Rexnord Corporation, All Rights Reserved. MCB24010E • Form# VM1-016E

RegalRexnord[™]